

PG Thread Adapter



PG Adapter




PG Adapter with Flexible Cordgrip



PG Adapter with Flexible Cordgrip, with CB Plug and Jacketed Cable

PG thread adapters fit all CB Series connectors with M14 x 1 accessory threads. These adapters accept all standard PG 7 liquid tight cordgrips.


Style 1

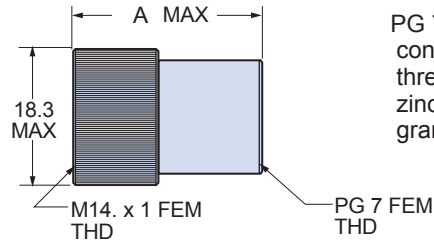

PG 7 adapter fits all CB Series connectors with M14 x 1 accessory thread. Aluminum alloy with black zinc plating. Maximum weight 6 grams.

Description	Part Number	A
Banding Adapter (Plug)	P-CBBSPG7-T	26.0
Banding Adapter (In-Line Receptacle)	R-CBBSPG7-T	23.0

Style 2

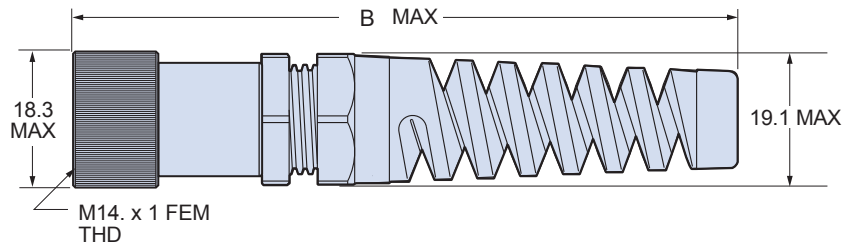

PG 7 adapter with liquid tight flexible cordgrip. Adapter fits all CB Series connectors with M14 x 1 accessory thread. Aluminum alloy with black zinc plating. Cordgrip is 6/6 nylon with thermoplastic elastomeric sealing gland. Fits cable diameter 3.5mm to 7mm. Supplied with nitrile O-ring for adapter-to-cordgrip seal. Maximum weight 15 grams.

Description	Part Number	B
Banding Adapter (Plug)	P-CBBSPG7CD-T	86.4
Banding Adapter (In-Line Receptacle)	R-CBBSPG7CD-T	83.4

Jam Nut Tightening Tool



Nickel-plated steel tightening tool fits jam nut receptacles. Fits 3/8 inch drive torque wrench. 18.5mm diameter, 25.4 mm length, 23 grams.

Part Number
600-146-04

Recommended installation torque: 6-7 N-m.