




# MISSION-CRITICAL UNDERWATER INTERCONNECT SOLUTIONS

Most aggressive lead times in the industry · Vertically integrated and made in the USA  
 Custom solutions, no minimum order quantities  
 Accessible and responsive engineering support · Obsessed with quality and qualification  
 Superior technical designs for extended durability and performance


## FULLY WIRED PBOF ASSEMBLIES

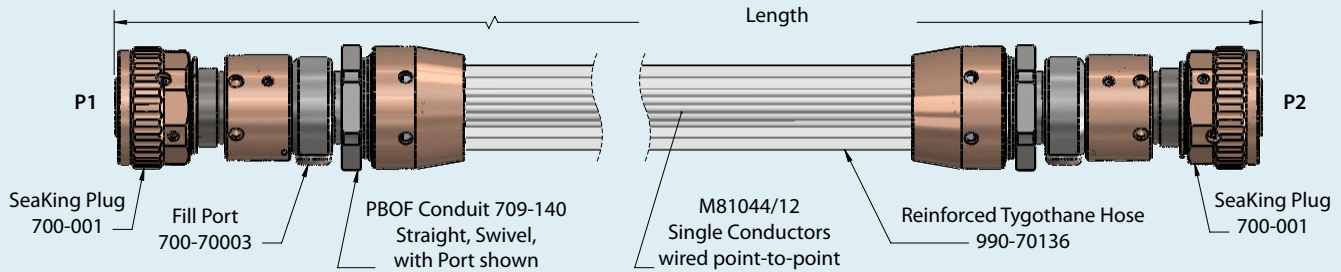

SeaKing PBOF Wired Assembly - How To Order						
Sample Part Number	7071-0348		-K19	-L1S	-L1S	-N -XXX
Base Part Number	7071-0348 = SeaKing™ PBOF wired assembly					
Insert Arrangement P1 and P2	G10, G8, K19, K14, K4, KC6, L9, M37, M26, M12, O61, O44, O19, OX49, Q109, Q30, R131 (see catalog or dwg 709-099 for details)					
End Configuration P1	Angle Option	Fill Port	Swivel/Fixed			
	L = Straight M = 45° N = 90°	1 = Yes 0 = No	S = Swivel F = Fixed			
End Configuration P2	Angle Option	Fill Port	Swivel/Fixed			
	L = Straight M = 45° N = 90°	1 = Yes 0 = No	S = Swivel F = Fixed			
Key Orientation	Key Position	A°		B°		
	N	150°		210°		
	A	75°		210°		
	B	95°		230°		
C	140°		275°			
Cable Length	in Inches					

## PBOF ACCESSORY KITS

SeaKing PBOF Attachment Accessory Kits - How To Order					
Sample Part Number	709-123	K	-L	1	S
Product Series	709-003 = SeaKing™ PBOF accessory				
Shell Size	E, G, K, L, M, O, P, Q, R				
Angular Function	L = Straight M = 45° N = 90°				
Fill Port Option	0 = No fill port 1 = With fill port				
Swivel/Fixed Option	S = Swivel F = Fixed				

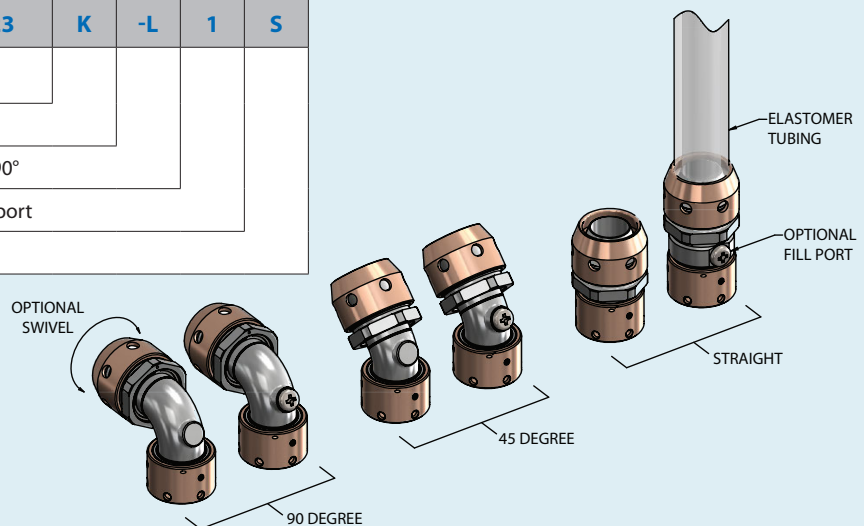


# SERIES 700 10K PSI / 700 BAR / 7000 M

## SeaKing™ High-Pressure Underwater Connectors, Cables, and PBOF Assemblies

### PBOF assembly fittings and accessories




#### CONNECTOR / BACKSHELL / BOOT SEAL ASSEMBLY

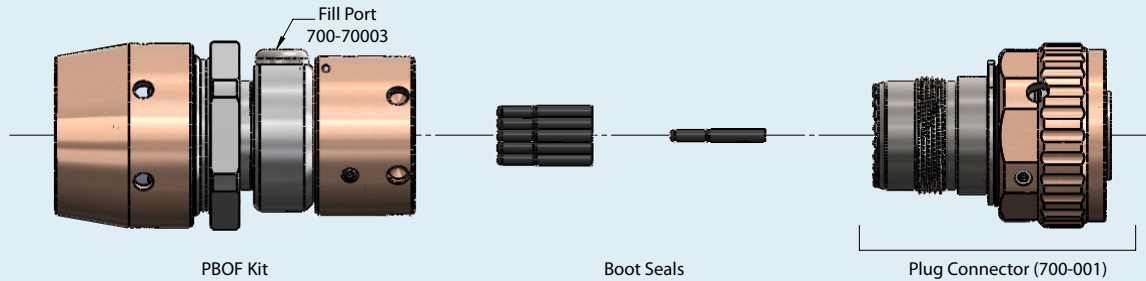

SeaKing PBOF Connector/Backshell/Boot Seal Assembly - How To Order						
Sample Part Number	707-0320	-K19	Z1	S	N	L1S
Base Part Number	707-0320 = SeaKing™ PBOF assembly					
Insert Arrangement	G10, G8, K19, K14, K4, KC6, L9, M37, M26, M12, O61, O44, O19, OX49, Q109, Q30, R131 (see catalog or dwg 709-099 for details)					
Barrel Material	Z1 = Stainless Steel TC = Titanium					
Contact Style	S = Socket					
Key Position	Key Position	A°	B°			
	N	150°	210°			
	A	75°	210°			
	B	95°	230°			
Configuration Options	Angle Option	Fill Port		Swivel/Fixed		
	L = Straight	1 = Yes		S = Swivel		
	M = 45°	0 = No		F = Fixed		
	N = 90°					

#### PBOF CONDUIT ASSEMBLIES

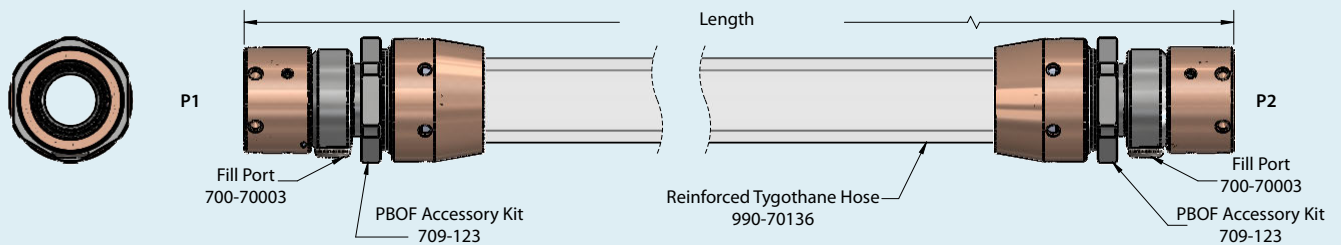

SeaKing PBOF Conduit Assembly - How To Order					
Sample Part Number	709-140	-K	-L1S	-L1S	-XX
Base Part Number	709-140 = SeaKing™ PBOF conduit assembly				
Backshell and Tubing size	E, G, K, L, M, O, P, Q, R				
Backshell Configuration P1	Angle Option	Fill Port		Swivel/Fixed	
	L = Straight	1 = Yes		S = Swivel	
	M = 45°	0 = No		F = Fixed	
	N = 90°				
Backshell Configuration P2	Angle Option	Fill Port		Swivel/Fixed	
	L = Straight	1 = Yes		S = Swivel	
	M = 45°	0 = No		F = Fixed	
	N = 90°				
Cable Length	in Inches				