

244-002

MIL-DTL-38999 Series III Type TVS Connector
Wall Mount Receptacle with RJ45 Jack To Rear Solder Cup or PC Tail
Termination and Standoffs



TVS Connectors



How to Order	
Sample Part Number	244-002 NF 19 P G N 1
Basic Number	244-002
Finish ¹	See Material & Finish Table
Shell Size ¹	17 or 19
Termination	P = PC tail S = Solder cup
Insert-to-Shell Grounding	G = Shielded and grounded to shell
Alternate Key Position ¹	Per MIL-DTL-38999 A, B, C, D, E, N = Normal
RJ45 Orientation	1, 2, 3, or 4


Materials and Finishes ¹	
NF	Cadmium olive drab
ME	Electroless nickel
MT	Nickel PTFE

NOTES

- See Section A for alternate key positions, panel cutout dimensions and complete finish options


All external dimensions, features, etc. compliant with D38999/20, /24, &/26. Consult factory for additional information.

RJ45 ORIENTATION CODE AND PCB LAYOUT (PCB LAYOUT FOR PC TAIL VERSION)

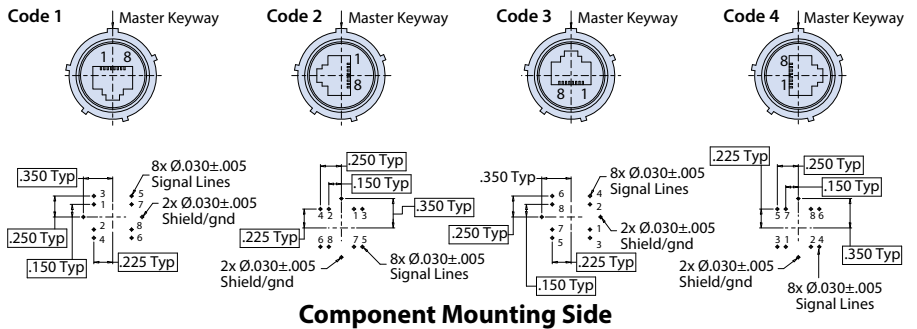

Component Mounting Side

Jam Nut Dimensions									
Shell Size	A Thread	B Sq.		C Bsc		Ø D Min.		E Bsc	
		in	mm	in	mm	in	mm	in	mm
17	1.1875-1P-.3L-TS-2A	1.323 1.299	33.60 32.99	1.062	26.97	1.219	30.96	1.062	26.97
19	1.2500-1P-.3L-TS-2A	1.449 1.425	36.80 36.195	1.156	29.36	1.297	32.94	1.156	29.36

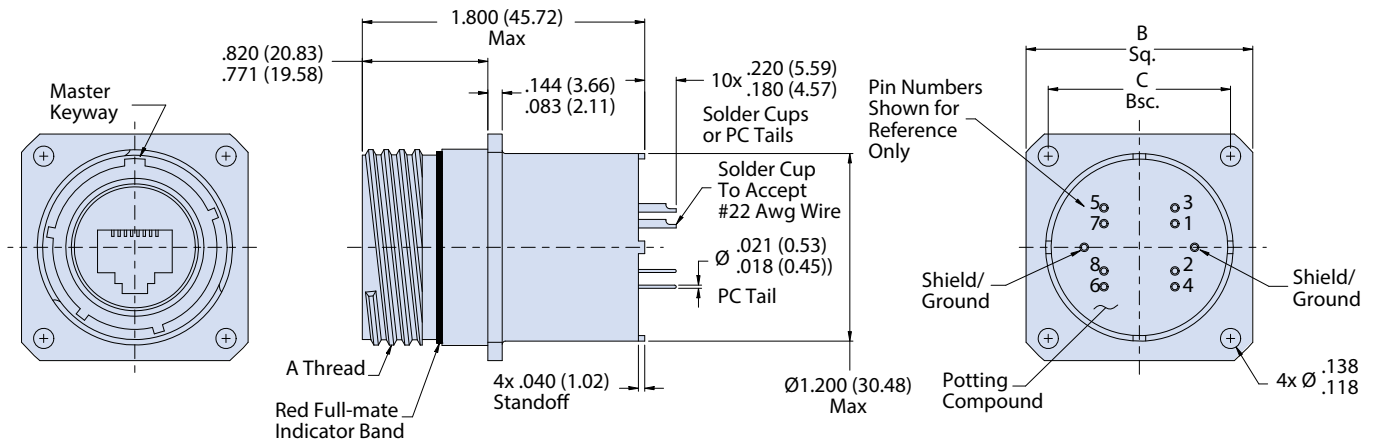

Dimensions in inches (millimeters) and are subject to change without notice.