




121-190 Annular Polymer-Core Convuluted Tubing with External Braid

Tubing plus a single EMI/RFI braided shield


B

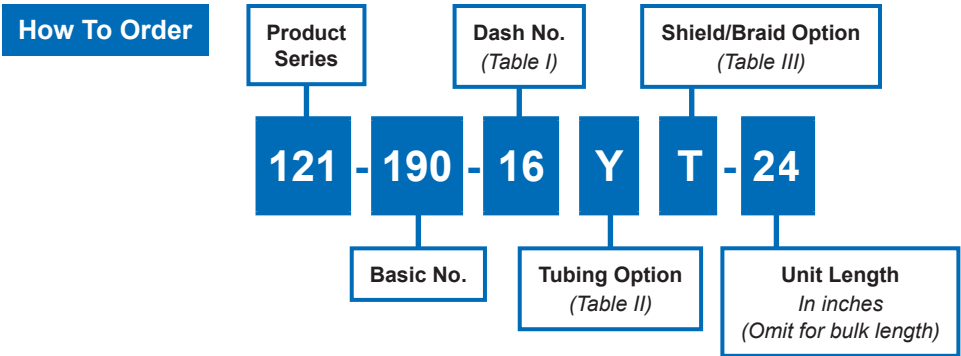

Dash No	A Inside Dia		B Outside Dia
	Min	Max	Max
06	.17 (4.3)	.19 (4.8)	.38 (9.6)
09	.24 (6.1)	.28 (7.1)	.48 (12.2)
12	.33 (8.4)	.37 (9.4)	.58 (14.7)
14	.40 (10.1)	.44 (11.2)	.65 (16.5)
16	.45 (11.4)	.50 (12.7)	.72 (18.3)
20	.57 (14.5)	.62 (15.7)	.83 (21.1)
24	.69 (17.5)	.75 (19.1)	1.00 (25.4)
28	.81 (20.6)	.87 (22.1)	1.14 (28.9)
32	.93 (23.6)	1.00 (25.4)	1.26 (32.0)
40	1.18 (30.0)	1.25 (31.8)	1.50 (38.1)
48	1.43 (36.3)	1.50 (38.1)	1.77 (44.9)
52	1.56 (39.6)	1.63 (41.4)	1.91 (48.5)

Y	Kynar/Thermally stabilized
V	PVDF/Not thermally stabilized
S	G-FLEX Siltem/Medium duty - natural color only

T	Tin/Copper
C	Stainless Steel
N	Nickel Copper
L	AarmorLite™
D	Dacron
M	Nomex
E	AmberStrand® 100%
F	AmberStrand® 75%/25%

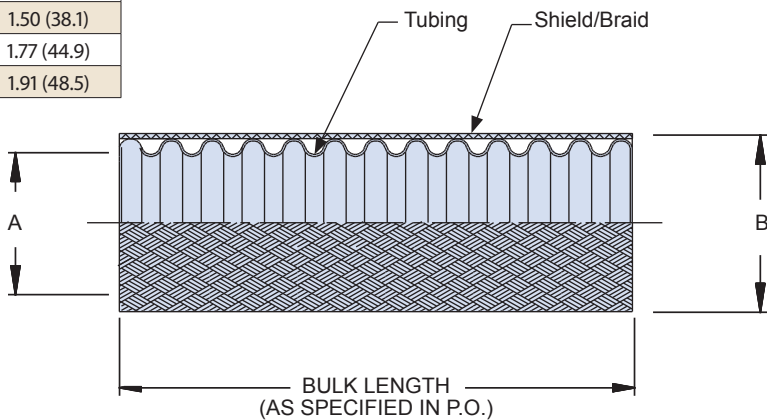

Dash No.	Max Length Per Pkg.
09&12	200 ft (60m)
16 - 52	100 ft (30m)

Packaging

Long-length orders of 121-190 braided conduit are subject to carrier weight and box size restrictions. For example, UPS air shipments are currently limited to 50 lbs. per box. Unless otherwise specified, Glenair standard practice is to ship optimal lengths of product based on weight, size, and individual carrier specifications. Consult factory for additional information or to specify packaging requirements.