

Series ITH Rigid Insert Reverse Bayonet Connectors


Dimensional Details

Socket Contacts



ITH
Rigid Insert
Connectors

Crimped Socket Contacts

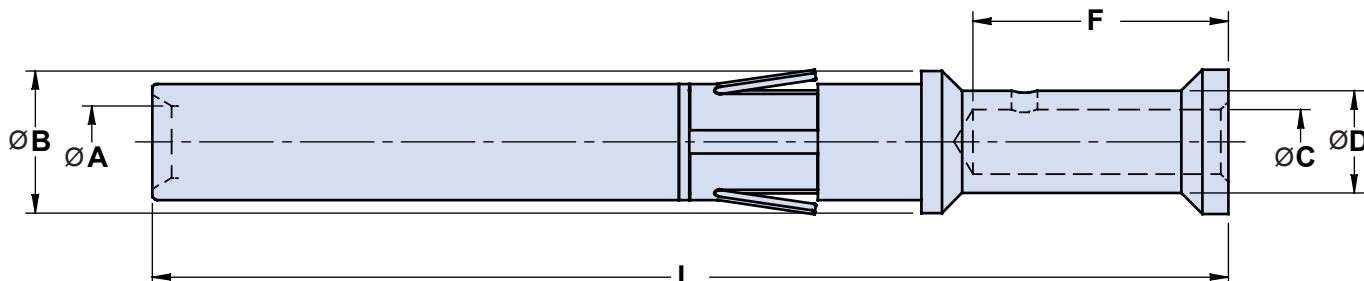

Part Number	Size	Wire gauge		ØA ±0.1	ØB +0 -0.1	ØC 0.1 -0	ØD ±0.1	F ±0.1	L ±0.2
		mm ²	AWG						
PL 40520	20	0.15 ÷ 0.6	26 ÷ 20	1.5	2.4	1.3	2	4.5	37.7
PL 40556	16	1.5	16	1.65	3.7	1.7	2.6	7.9	34.9
PL 40556-12	16	0.5 ÷ 0.75	20	1.65	3.7	1.2	2.6	7.9	34.9
PL 40556-15	16	1	18	1.65	3.7	1.5	2.6	7.9	34.9
PL 40556-20	16	2	14	1.65	3.7	2	2.9	7.9	34.9
PL 40556-26	16	2.5 ÷ 3.5	12	1.65	3.7	2.5	3.8	7.9	34.9
PL 40560	12	2.5 ÷ 3.5	12	2.45	5.5	2.5	3.9	9.9	37.9
PL 40560-12	12	0.5 ÷ 0.75	20	2.45	5.5	1.2	2.6	9.9	37.9
PL 40560-20	12	1 ÷ 2	18 ÷ 14	2.45	5.5	2	3.9	9.9	37.9
PL 40560-30	12	4		2.45	5.5	3	4.8	9.9	37.9
PL 40793	8	6 ÷ 8	8	3.65	8.2	4.5	6.9	12.2	41.8
PL 40793-30	8	4		3.65	8.2	3	4.8	12.2	41.8
PL 40793-38	8	6		3.65	8.2	3.60	6.80	12.2	41.8
PL 40793-50	8	10		3.65	8.2	5.00	6.90	12.2	41.8

Size 8 Coaxial Contact

