


Series 804 Push/Pull Mighty Mouse USB Tactical Patch Cable 808-007 Interface Adapter




Series 804

These cordsets feature ruggedized series 804 Mighty Mouse Push/Pull connectors in a size #6 shell with insert arrangements for 6 pins for both plug and receptacle. Polyurethane cable jacket is suitable for general purpose applications. Mighty Mouse connector is overmolded with polyamide for strain relief and water ingress protection. All pin connectors have first to mate, last to break (FMLB) contact in position 2.

Note: Cable Type D shown for reference only. See Table I and II for Ordering information on polyurethane or Nomex® jacketed cable types.

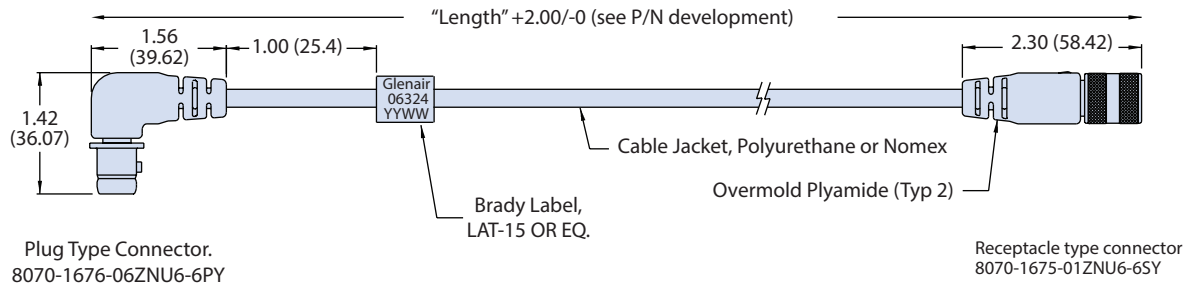

Wiring Diagram

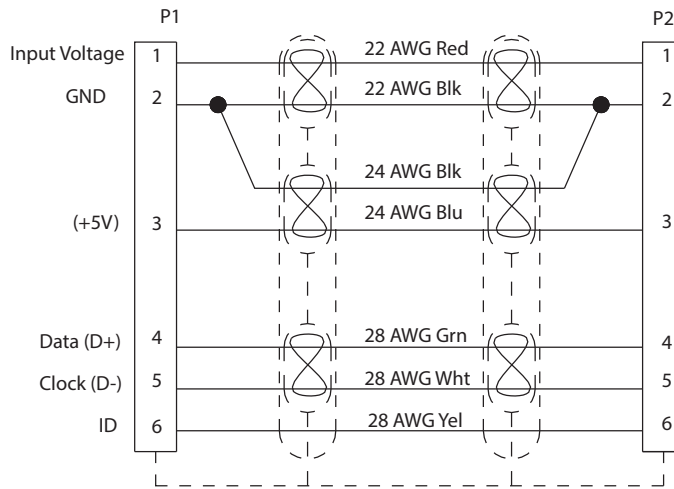

Dimensions in Inches (millimeters) are subject to change without notice.





Series 804 Push/Pull Mighty Mouse USB Tactical Patch Cable with Polyurethane Jacket 808-007 Interface Adapter

Table I: How To Order Cables with Polyurethane Cable Jacket

Basic P/N	Cable Type	Length	
808-007	-A = Single Ended -AA = Double Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-A	12	
808-007	-B = Single Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-B	12	
808-007	-C = Single Ended -CC = Double Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-C	12	
808-007	-D = Single Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-D	12	
808-007	-E = Single Ended -EE = Double Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-E	12	

Dimensions in Inches (millimeters) are subject to change without notice.

Series 804 Push/Pull Mighty Mouse USB Tactical Patch Cable with Nomex® Jacket 808-007 Interface Adapter



Series 804

Table 2: How To Order Cables with Nomex Jacket

Basic P/N	Cable Type	Length	
808-007	-G = Single Ended -GG = Double Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-G	12	
808-007	-H = Single Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-H	12	
808-007	-J = Single Ended -JJ = Double Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-J	12	
808-007	-K = Single Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-K	12	
808-007	-L = Single Ended -LL = Double Ended	In inches 12 = 12 in.	
Sample Part Number			
808-007	-LL	12	

Dimensions in Inches (millimeters) are subject to change without notice.

