




# Series 844 Stinger™ Mighty Mouse Push-Pull Plug

844-001 and 844-002 - Shell Style 06 Dimensions

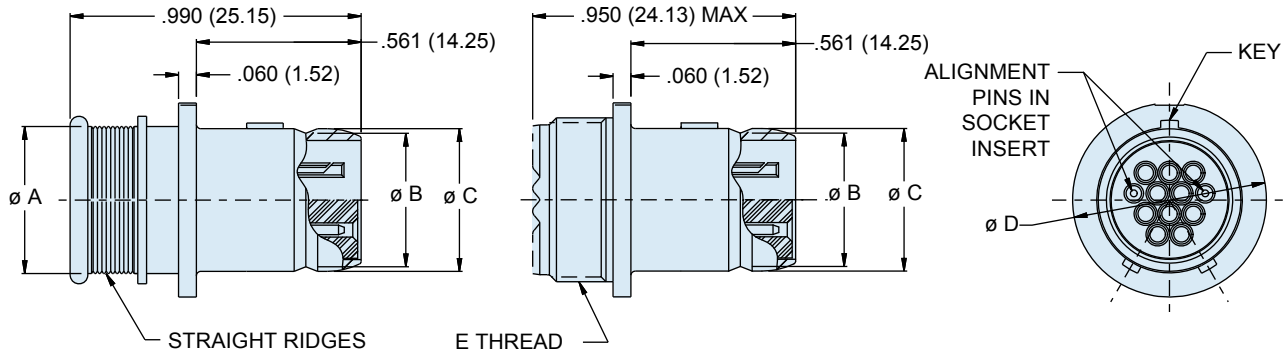

**Integral Band Platform**  
841-001-06

**Accessory Thread**  
841-002-06



Dimensions									
Shell Size	Ø A		Ø B		Ø C		Ø D Max		E Thread
	In	mm	In	mm	In	mm	In	mm	
5	0.246	6.25	0.219	5.56	0.250	6.35	0.427	10.85	.2500-32 UNEF-2A
6	0.286	7.26	0.282	7.16	0.313	7.95	0.495	12.57	.3125-32 UNEF-2A
7	0.390	9.91	0.351	8.92	0.383	9.73	0.575	14.61	.4375-28 UNEF-2A
8	0.442	11.23	0.398	10.11	0.429	10.90	0.614	15.60	.5000-28 UNEF-2A
9	0.500	12.70	0.454	11.53	0.486	12.34	0.670	17.02	.5625-24 UNEF-2A
10	0.564	14.33	0.529	13.44	0.563	14.30	0.745	18.92	.6250-24 UNEF-2A
11	0.608	15.44	0.587	14.91	0.618	15.70	0.795	20.19	.6875-24 UNEF-2A

Table II: Key Positions		
	A°	B°
<b>A</b>	150°	210°
<b>B</b>	75°	210°
<b>C</b>	95°	230°
<b>D</b>	140°	275°
<b>E</b>	75°	275°
<b>F</b>	95°	210°

Dimensions in Inches (millimeters) are subject to change without notice.