



Alternate key and keyway polarization

REFERENCE INFORMATION

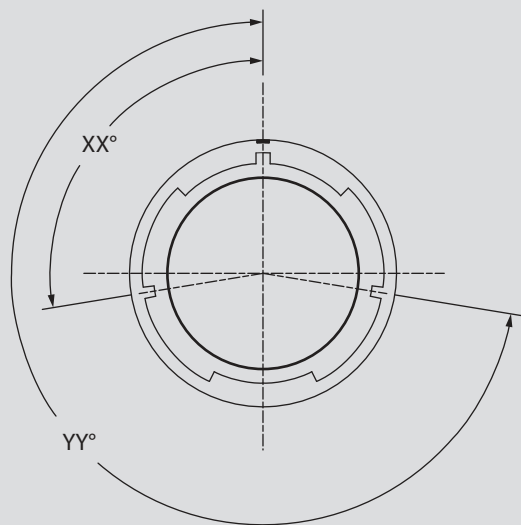

Alternate Key and Keyway Receptacles

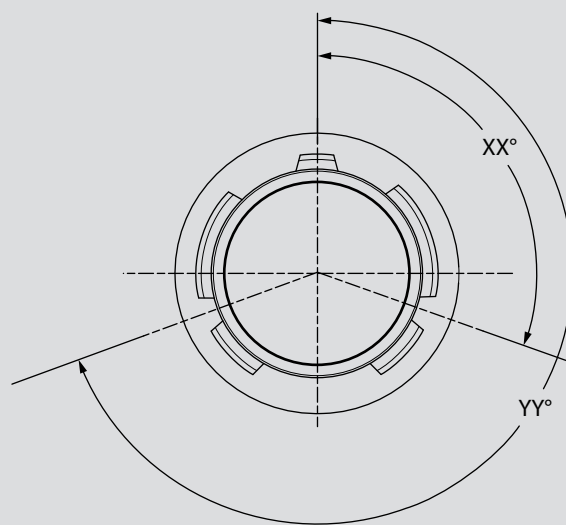

Alternate Key and Keyway Plugs

Series IV Alternate Key and Keyway Polarization		
Polarization	XX°	YY°
N	110°	250°
A	100°	260°
B	90°	270°
C	80°	280°
D	70°	290°
K	120°	255°
L	120°	265°
M	120°	275°
R	120°	285°