




D-Subminiature Backshells Jackscrew Options


JACKSCREW - STYLE E (END ENTRY)

Type J Knurled Slotted Head


All jackscrews have 4-40 UNC-2A threads to mate with M24308/26 female screwlocks or 559-001 mounting kits. Not applicable for cable-to-cable applications.

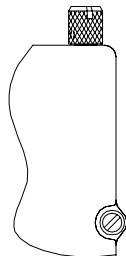


MALE JACKSCREW OPTIONS

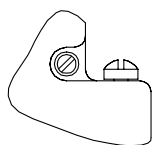


Type B
Fillister Head

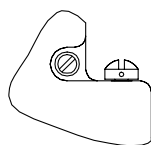


Type D
Drilled
Fillister Head

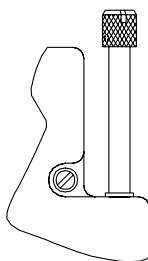

Type E *
Extended Knurled
Slotted Head

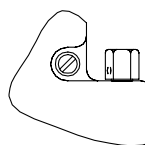

Type H
Hex Head

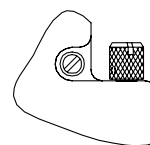


Type K *
Knurled Slotted
Head


Unless otherwise noted, all jackscrews have 4-40 UNC-2A threads to mate with M24308/26 female screwlocks or 559-001 mounting kits. Not applicable for cable-to-cable applications.

* Not available for Style "E" (end entry backshells).


POLARIZING JACKSCREW OPTIONS

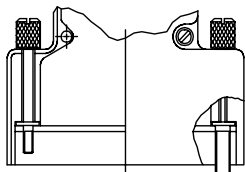


Type F
Turnable Male & Female

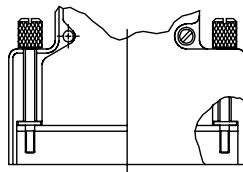


Type M
Turnable Males

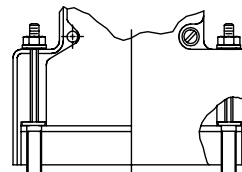


Type P
Fixed Females

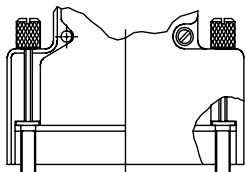

Type L
Turnable Females

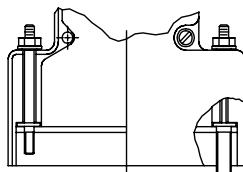

Type N
Fixed Male & Female

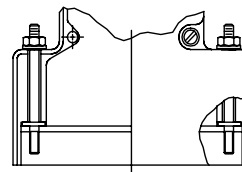

Type R
Fixed Males