

527-128 Solid G-Spring EMI/RFI Backshell for Cannon DPXA Series Connectors

527-128 M 01 L

Basic Part No. _____

Finish Symbol (Table II) _____

Dash No. (Table I, Note 2) _____


Entry Location: _____

L = Left Entry
R = Right Entry
T = Top Entry

Symbol	Finish
B	Cadmium Plate, Olive Drab
J	Iridite, Gold Over Cadmium Plate over Nickel
M	Electroless Nickel
N	Cadmium Plate, Olive Drab, Over Nickel
NF	Cadmium Plate, Olive Drab, Over Electroless Nickel (500 Hour Salt Spray)
T	Cadmium Plate, Bright Dip Over Nickel (500 Hour Salt Spray)

Dash No.	A Max	Cable Range	
		Min	Max
01	.968 (24.6)	.156 (4.0)	.375 (9.5)
02 *	1.218 (30.9)	.375 (9.5)	.625 (15.9)

* See Note 2

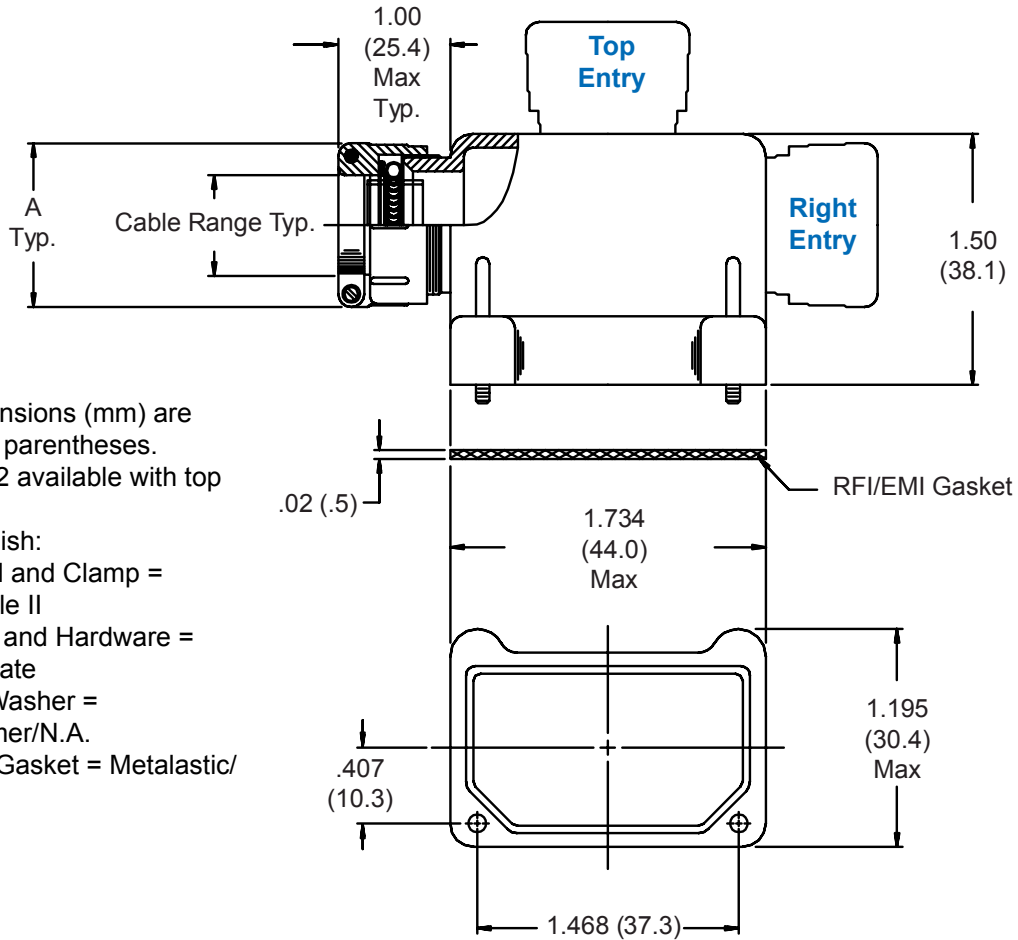

- Metric dimensions (mm) are indicated in parentheses.
- Dash No. 02 available with top entry only.
- Material/Finish:
Backshell and Clamp = Al Alloy/Table II
G-Spring and Hardware = SST/Passivate
Friction Washer = Fluoropolymer/N.A.
EMI/RFI Gasket = Metalastic/N.A.