

Coax Contacts

For Multi-Port Military/Aerospace Connectors




852-130
852-131

852-251

- Size 16
- 50 Ohm

- Solder Termination
- 4 GHz

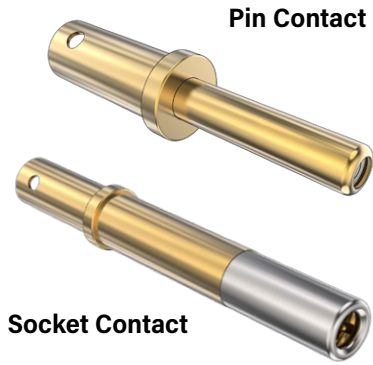

Pin Contact

Socket Contact

4 GHz, 50 ohm, Size 16. Snap-in, rear release coax contacts fit MIL-DTL-38999 connectors and Glenair connectors with size 16 contact cavities. Solder termination. Supplied unassembled with assembly instructions.

PART NUMBER			
	Pin Contact	Socket Contact	
	<ul style="list-style-type: none"> ■ Series 790, 791 ■ Series 80 ■ Series 806 ■ M38999 I, II, III, IV ■ Series 233, 234 	<ul style="list-style-type: none"> ■ Series 790, 791 ■ Series 80 ■ Series 806 ■ M38999 Series II 	
Coax Cable		<ul style="list-style-type: none"> ■ M38999 Ser. I, III, IV ■ Series 233, 234 	
RG405-FLEX 962-010-405 (Glenair)	852-130-01	852-131-01	852-251-01
M17-93-RG178	852-130-02	852-131-02	852-251-02

COAX CONTACTS

CONNECTOR COMPATIBILITY

- MIL-DTL-38999 Series I, II, III, IV
- Series 790 & 791 Micro-Crimp
- Series 80 Mighty Mouse
- Series 23 SuperNine
- Series 806 Mil-Aero


CONSTRUCTION

- Center contact, body, ferrule: copper alloy, gold over nickel plating
- Dielectrics: fluoropolymer
- Socket contact hood: SST, passivated


SPECIFICATIONS

- Operating temperature: -55 °C to +125 °C
- Frequency range: DC - 4 GHz
- Impedance: 50 ohms
- VSWR: 1.30:1
- Dielectric withstanding voltage: 325 Vdc
- Insulation resistance: 5,000 megohms
- Durability: 500 mating cycles

852-130 PIN

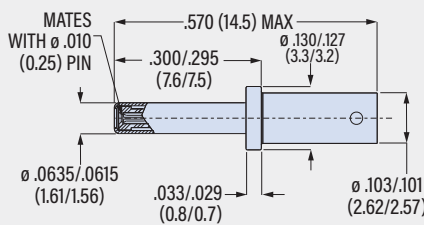

852-251 SOCKET

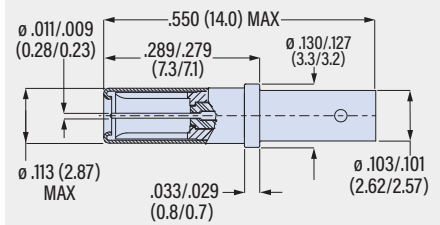

852-131 SOCKET

