


SuperNine RF Insert Arrangements

SuperNine RF Size 8 Contact Arrangements

Optimized for Size #8 BMB Contacts

Cable Diameter: .305" Max

Max Frequency: 18 GHz

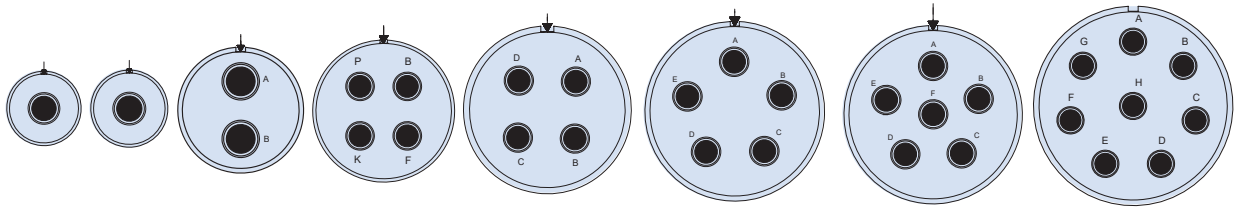


Arrangement No.	9RF5 Shell Sz. 9 1 contact	11RF1 Shell Sz. 11 1 contact	17RF75 Shell Sz. 17 2 contacts	19RF4 Shell Sz. 19 4 contacts	21RF75 Shell Sz. 21 4 contacts	23RF5 Shell Sz. 23 5 contacts	23RF6 Shell Sz. 23 6 contacts	25RF8 Shell Sz. 25 8 contacts
-----------------	---	---	---	--	---	--	--	--

SuperNine RF Size 12 Contact Arrangements

Optimized for Size #12 SMPM Contacts

Cable Diameter: .150" Max

Max Frequency: 40 GHz

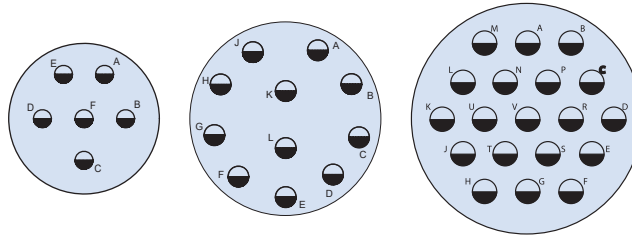


Arrangement No.	17RF6 Shell Sz. 17 6 contacts	21RF11 Shell Size 21 11 contacts	25RF19 Shell Size 25 19 contacts
-----------------	--	---	---

SuperNine RF Size 16 Contact Arrangements

Optimized for Size #16 SMPM Contacts

Cable Diameter: .086" Max

Max Frequency: 65 GHz

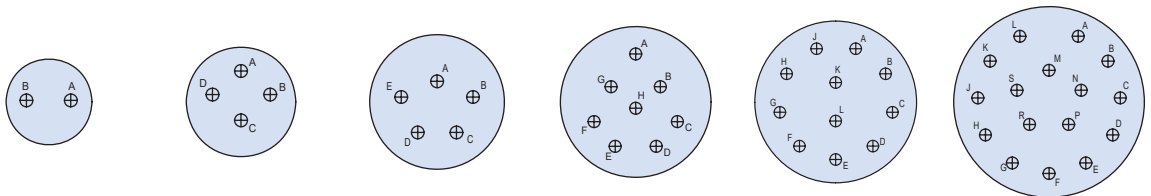


Arrangement No.	11RF2 Shell Sz. 11 2 contacts	13RF4 Shell Sz. 13 4 contacts	15RF5 Shell Sz. 15 5 contacts	17RF8 Shell Sz. 17 8 contacts	19RF11 Shell Sz. 19 11 contacts	21RF16 Shell Size 21 16 contacts
-----------------	--	--	--	--	--	---

Optimized for Size #16 SMPM Contacts

Cable Diameter: .086" Max

Max Frequency: 65 GHz

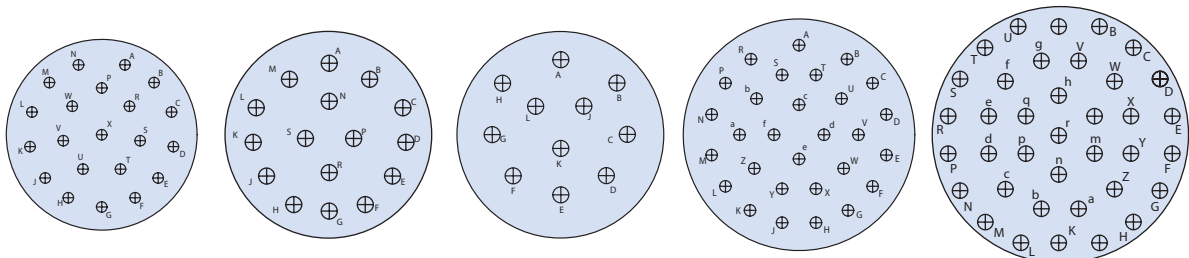

Arrangement No.	23RF21 Shell Size 23 21 contacts	23RF97 Shell Size 23 16 contacts	23RF99 Shell Size 23 11 contacts	25RF29 Shell Size 25 29 contacts	25RF37 Shell Size 25 37 contacts
-----------------	---	---	---	---	---

SUPERNINE MULTI-PIN RF CONNECTORS