



# IGE-MB

NO  
MINS.  
No Dollar  
or quantity  
Minimum Orders

## Reverse Bayonet Single-Pole Connectors VG96929 Compliant Marine Bronze Series


**IGE-MB** High Power Single Pole Connectors are used with cables from 16 to 240 mmq. These connectors achieve high-performance working current and peak current, and are ideal for engines, power supplies, and power distribution boxes. Several backshells are available, either straight or 90° elbows for the most reliable cable accommodation. See the VG96929 Catalogue for detailed electrical characteristics. IP67 protection is the standard performance. IP68 on request.

For further details and drawings about these connectors, and for a wider choice of backshell classes and connector shell styles, please refer to the related Glenair standard catalogue "VG96929 Series Connectors"

### How To Order

### Modifications

- 03** - Connector with Shrink Boot Adapter
- 04** - Square Flange Rear Mount Receptacle with Crimp Contact
- 14** - Connector with Adapter for Braided EMI Shield and Shrink Boot
- 16** - Square Flange Front Mount Receptacle with Threaded Contact

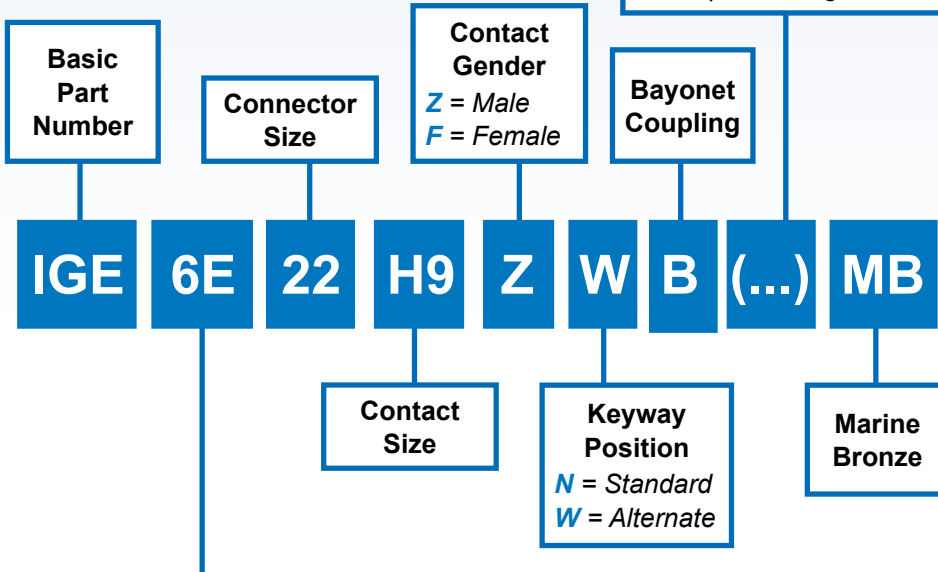

### Connector Shell Styles

- 0E** - Square Flange Rear Panel Mounted Receptacle, Threaded Holes. Shrink Boot Adapter
- 1E** - In-Line Receptacle with Shrink Boot Adapter
- 2E** - Square Flange Front Panel Mounted Receptacle with Threaded Mounting Holes
- 2EFP** - Square Flange Front Panel Mounted Receptacle with Through Mounting Holes
- 6E** - Straight Plug with Grounding Fingers and Adapter for EMI/RFI Shield and Shrink Boot
- 8E** - 90° Plug with Grounding Fingers and Adapter for EMI/RFI Shield and Shrink Boot
- 9E** - Square Flange Rear Mounted Through Bulkhead Receptacle with Threaded or Optional Thru Holes