

## ITB 07TF-XX Jam Nut Connector Cap with Stainless Steel Wire Rope

Basic Part Number and  
Shell Size Designator  
(Table I)

Length (in mm)  
Omit for Standard Length  
(Table I)


Material/Finish Options  
(Table II)

**ITB**

**07TF-32**

**-XXX**


**XX**

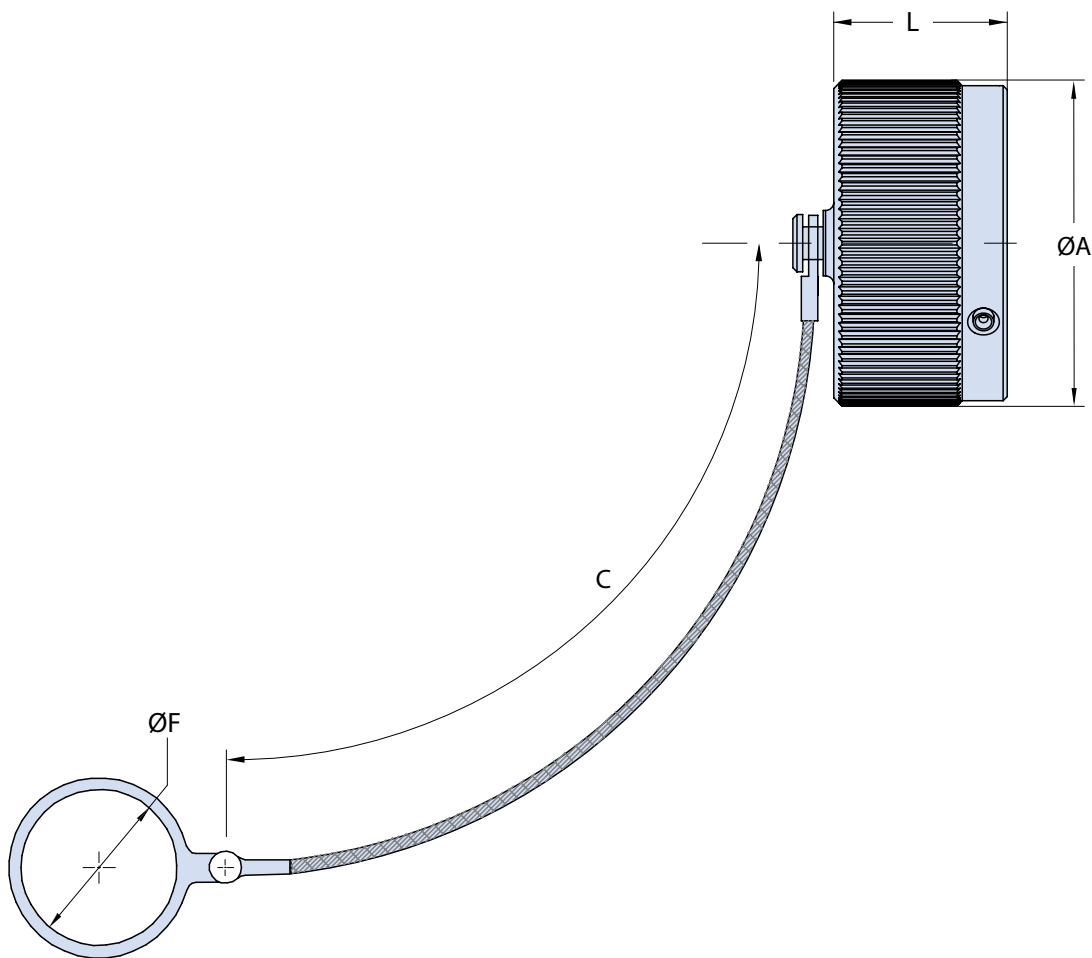

### Application Notes

1. Metal protective cap for bayonet receptacle connectors with stainless steel wire rope.
2. Standard materials configuration consists of aluminum alloy. For platings, see TABLE II finish options.

**ITB 07TF-XX**  
**Jam Nut Connector Cap**  
**with Stainless Steel Wire Rope**

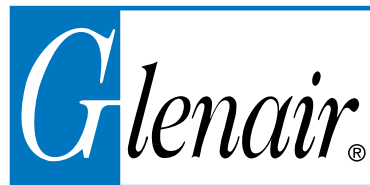

**TABLE I: RECEPTACLE CONNECTOR CAP PART NUMBERS, CONNECTOR SIZE AND DIMENSIONS**

Part Number	Connector Size	ØA ±0.5	C Min.	ØF +0.3 -0.1	L Max.
ITB 07TF -10SL	10SL	22.6	208	22.65	16.0
ITB 07TF -14S	14S	29.0	208	29.00	16.0
ITB 07TF -16	16S	32.0	208	32.15	16.0
ITB 07TF -17	16	32.0	208	32.15	21.0
ITB 07TF -18	18	36.5	208	35.35	21.7
ITB 07TF -20	20	39.8	208	38.50	21.7
ITB 07TF -22	22	43.0	208	41.00	21.7
ITB 07TF -24	24	46.4	208	45.00 (!)	21.7
ITB 07TF -28	28	53.0	208	51.20 (!)	21.7
ITB 07TF -32	32	60.0	208	57.50 (!)	21.7
ITB 07TF -36	36	66.2	208	63.80 (!)	21.7
ITB 07TF -40	40	72.3	208	70.20 (!)	21.7

(!) Please contact the factory.

**TABLE II**

STANDARD MATERIAL AND FINISH (*)		
Sym	Description	RoHS
	Omit for Aluminum/ Cadmium Olive Drab	
F6	Aluminum/ Black Electrodeposited Paint	✓
F7	Aluminum/ Black Zinc Nickel	✓
F11	Aluminum/ Electroless Nickel	✓
MB	Marine Bronze/ Unplated	✓
FK	Stainless Steel/ Passivate	✓

(\*) For further options, please contact the factory.