


.062" PITCH COMPLIANT PIN

HD Stacker™

GSTT-PF PC tail pin connector
with threaded hardware




MATES WITH GSTB

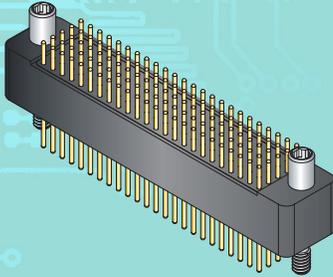

- Innovative Chevron Contact System (CCS)
- High-density layouts from 40 to 240 contacts
- Polarized insulators
- Keyed guide pin hardware for mis-mate protection
- Turnkey PC-tail flex jumpers available from Glenair, consult factory.




All Glenair HD Stacker™ connectors are equipped with our innovative .062" pitch high-density Chevron Contact System (CCS). Special non-orthogonal socket tines enable both higher density layouts as well as improved signal integrity. The GSTT-PF is equipped with pin contacts and PC tails for termination to flex

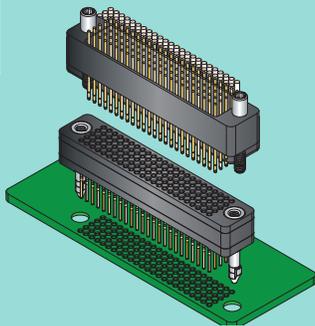

The GSTT-PF is a top-of-stack connector for termination to flex. Shown: GSTT-PF stack-mating with GSTB.

How to Order GSTT-PF HD Stacker Connectors						
Sample Part Number	GSTT	-120	P	F	-.080	M
Series	GSTT = PC Tail Top Stacker (For Flex Termination)					
Number of Contacts	40, 80, 120, 160, 200, 240					
Contact Type	P = Pin					
Termination Type	F = PC Tail (For Flex Termination)					
PC Tail Length	.080, .110, .140, .172, .190, .250					
Hardware*	M = Hex Head Jackscrew					

*Connectors with 40 to 160 positions have #2-56 threads, connectors with 200 to 240 positions have #4-40 threads

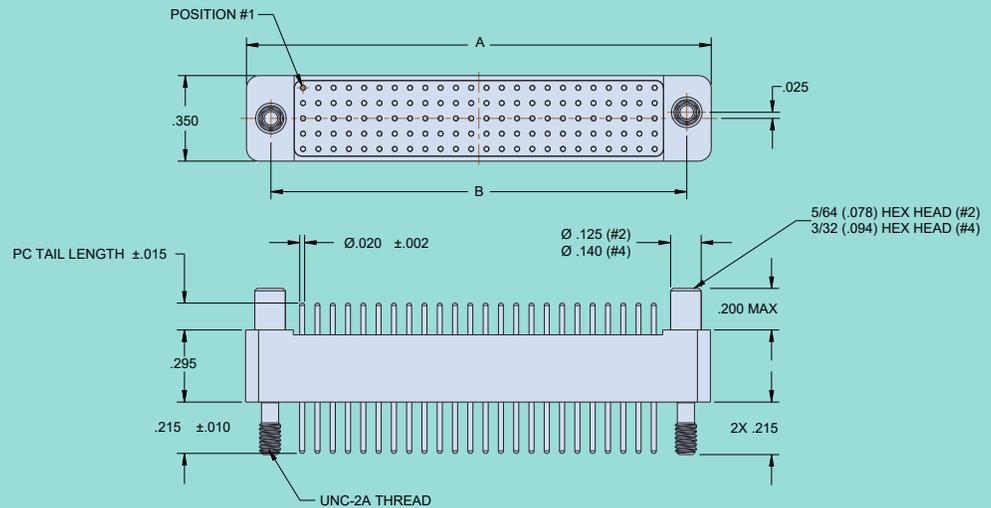

Number of Contacts	A		B	
	in	mm	in	mm
40	0.90	22.86	0.70	17.78
80	1.40	35.56	1.20	30.48
120	1.90	48.26	1.70	43.18
160	2.40	60.96	2.20	55.88
200	2.90	73.66	2.70	68.58
240	3.40	86.36	3.20	81.28

.062" PITCH COMPLIANT PIN

HD Stacker™

GSTT-PF PC-tail (flex) connector

Top-of-stack



FLEX LAYOUTS (COMPONENT SIDE)

