

SERIES 86


# SealTac Tactical Push-Pull Connectors

## 861-004 cable jumper SuperSpeed USB 3.0


MIGHTY MOUSE SEALTAC

How To Order	
<b>Sample Part Number</b>	<b>861-004-B ZR A -36</b>
<b>Series</b>	<b>861-004-A</b> = target contact push-pull plug-to-USB 3.0 overmolded cable jumper <b>861-004-B</b> = spring contact push-pull receptacle-to-USB 3.0 overmolded cable jumper
<b>Material / Finish</b>	<b>ME</b> = Aluminum Electroless Nickel <b>ZR</b> = Aluminum / Black Zinc Nickel <b>Z1</b> = 316 Stainless Steel / Passivated
<b>Key Position</b>	<b>A</b> = Normal <b>B</b> = Pos. B <b>C</b> = Pos. C <b>D</b> = Pos. D <b>E</b> = Pos. E <b>F</b> = Pos. F
<b>Cable Length</b>	Cable length, "L" in inches, 72 inches max.

861-004-A Mighty Mouse SealTac Plug-to-USB 3.0 jumper

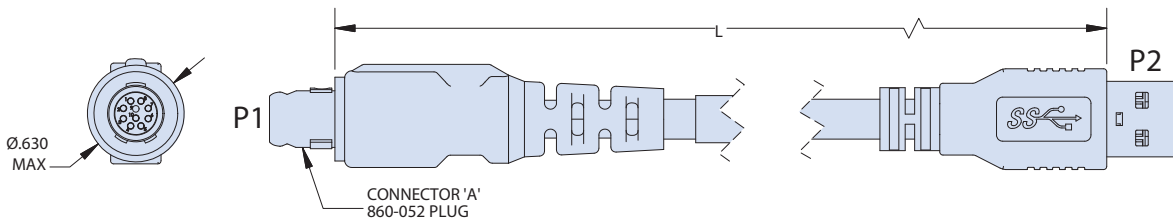

861-004-B Mighty Mouse SealTac Receptacle-to-USB 3.0 jumper

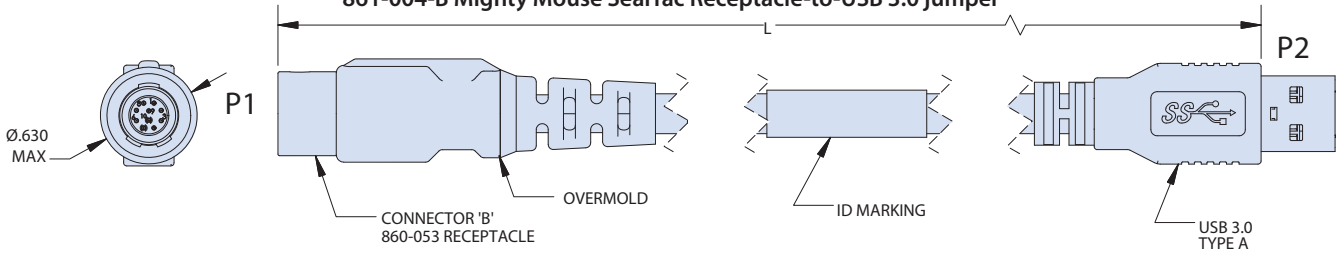

### MATERIAL / FINISH

- Plug connectors IAW 860-052 (plug) and 860-053 (receptacle)
- Overmold: TPV elastomer, black
- Cable: Low-smoke zero-halogen black jacket

### TECHNICAL SPECIFICATIONS

- Temperature range -10°C to +75°C
- 100% electrical testing, pin-pin and pin-shell DWV: 100 VAC min, IR = 100 MΩ min at 100 VDC, and continuity check