
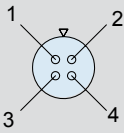
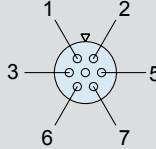
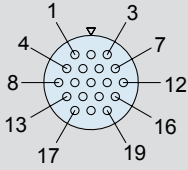
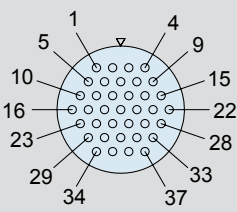
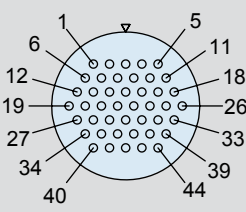
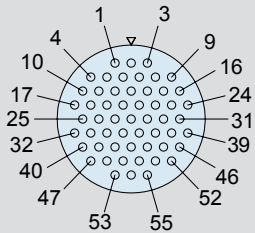


Circular Shell Size/Contact Arrangements and Keying Positions

A

Circular Plug Mating Face Views		
Size 1-4, 4 Contacts	Size 1-7, 7 Contacts	Size 2-19, 19 Contacts
		
Size 3-37, 37 Contacts	Size 4-44, 44 Contacts	Size 4-55, 55 Contacts
		







Position identifications are for reference only and do not exist on actual connector

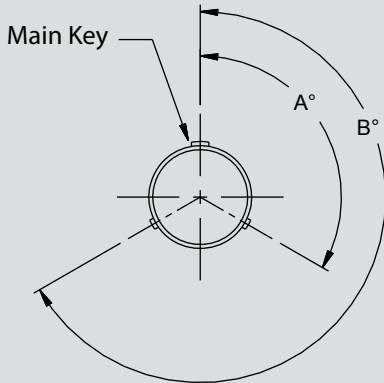

Key Positions			
Size	Polarization	A°	B°
1-4	N	150	210
	A	75	210
1-7	N	95	230
	A	140	275
2-19	N	150	210
	A	75	210
3-37	N	150	210
	A	75	210
4-44	N	150	210
	A	75	210
4-55	N	95	230
	A	140	275

Circular Shell Size/Contact Arrangements and Keying Positions

A

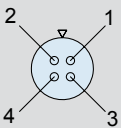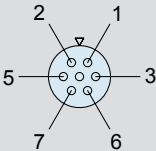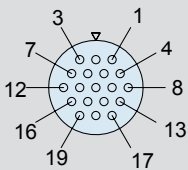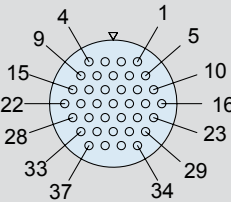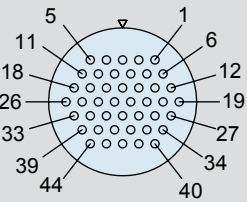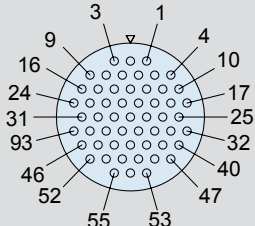Circular Receptacle Mating Face Views		
Size 1-4, 4 Contacts	Size 1-7, 7 Contacts	Size 2-19, 19 Contacts
		
Size 3-37, 37 Contacts	Size 4-44, 44 Contacts	Size 4-55, 55 Contacts
		

Position identifications are for reference only and do not exist on actual connector

Key Positions			
Size	Polarization	A°	B°
1-4	N	150	210
	A	75	210
1-7	N	95	230
	A	140	275
2-19	N	150	210
	A	75	210
3-37	N	150	210
	A	75	210
4-44	N	150	210
	A	75	210
4-55	N	95	230
	A	140	275

