




Cable Connectors Environmental

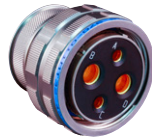

Plug with
Accessory Thread
970-001
Page 17



Plug with
Banding Platform
970-011
Page 19



Receptacle with
Accessory Thread
970-005
Page 21



Receptacle with
Banding Platform
970-033
Page 23




Overmolded
Turboflex Cordsets
Page 25


Square Flange Receptacles, Environmental




Square Flange Receptacle
with Accessory Thread
970-003
Page 26

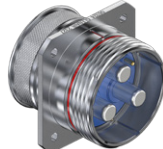


Square Flange Receptacle
with Banding Platform
970-032
Page 28

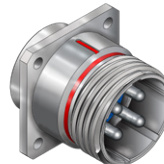

Low Profile Square Flange
Receptacle
970-009
Page 30

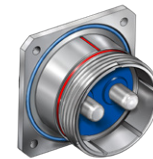

Low Profile Square Flange
Receptacle w/ O-ring
970-013
Page 32

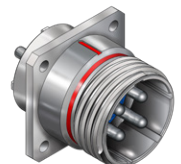

Square Flange Receptacle
w/ PC Tails
970-008
Page 34

Jam Nut Receptacles, Environmental



Jam Nut Receptacle
with Accessory Thread
970-004
Page 37



Jam Nut Receptacle
with Banding Platform
970-031
Page 39




Low Profile Jam Nut
Receptacle
970-010
Page 51




Feed-Thru Bulkhead J/N
Receptacle
970-006
Page 53

Hermetic Receptacles

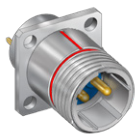

Square Flange Hermetic
Receptacle
970-012
Page 45

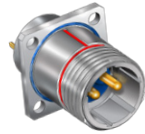

Square Flange Hermetic
Receptacle w/ O-ring
970-030
Page 47



Square Flange Hermetic
Receptacle w/ Crimp Contacts
970-038
Page 49



Jam Nut Hermetic
Receptacle
970-025
Page 51



CODE RED Lightweight Jam
Nut Feed-Thru Bulkhead
Hermetic Receptacle
970-041
Page 53




Jam Nut Feed-Thru
Bulkhead Hermetic
Receptacle
970-007
Page 55



Jam Nut Feed-Thru
Bulkhead Hermetic
Receptacle w/ (2) O-rings
970-026
Page 57

Filter Receptacles

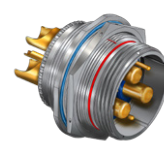

Jam Nut
Filter Receptacle
240-970J
Page 59



Square Flange
Filter Receptacle
240-970W
Page 59