


962-025-047 BLUMARK RF COAX CABLE, CONNECTOR CONTACT, AND MULTI-PORT HOUSING COMPATIBILITY MATRIX



Pin Contact

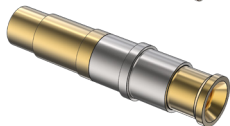

Socket Contact

Size 12 for use with  
-047 cable  
40 GHz SMPM interface  
50 Ohm

Solder termination


Snap-in, rear release  
pin and socket coax  
contacts, spring-loaded.



962-025-047

BLUMARK  
COAX CABLES RF

- 50 ohm size 047 (.056" jacket diameter, .011" conductor), 70 GHz maximum bandwidth low-attenuation cable
- -65 to +165 °C rated operating temperature
- FEP jacket, PFA dielectric, solid SPC center conductor
- Double-shielded: Tape/braid shield layers with >90 dB shield effectiveness

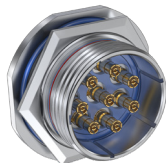


Series 23 SuperNine

"Better than QPL" MIL-DTL-38999 Series III



Series 806 RF Mil-Aero

Micro miniature circular IAW D38999

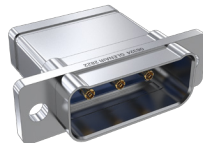

Series 795 RF

High-performance multi-port rectangular



VITA 67.3 RF

VPX modular connection system

852-099-03 Pin	✓	✓	✓	
852-154-03 Socket	✓			
852-100-03 Socket		✓	✓	
852-304-01 (Module, Center Pin)				✓
852-305-01 (Backplane, Center Socket)				✓