 


962-025-047 BLUMARK RF COAX CABLE, CONNECTOR CONTACT, AND MULTI-PORT HOUSING COMPATIBILITY MATRIX

Pin Contact



Socket Contact


Size 16 for use with
-047 cable
65 GHz SMPS interface
50 Ohm
Solder termination
Snap-in, rear release
pin and socket coax
contacts, spring-loaded.



962-025-047

BLUMARK
COAX CABLES RF

- 50 ohm size 047 (.056" jacket diameter, .011" conductor), 70 GHz maximum bandwidth low-attenuation cable
- -65 to +165 °C rated operating temperature
- FEP jacket, PFA dielectric, solid SPC center conductor
- Double-shielded: Tape/braid shield layers with >90 dB shield effectiveness

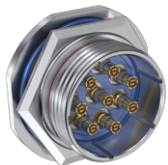

Series 23 SuperNine

"Better than QPL" MIL-DTL-38999 Series III



Series 806 RF Mil-Aero

Micro miniature circular IAW D38999



Series 795 RF

High-performance multi-port rectangular

852-133-01 Pin



852-134-01 Socket



852-251-01 Socket

