

962-025-086 BLUMARK RF COAX CABLE, CONNECTOR CONTACT, AND MULTIPOINT HOUSING COMPATIBILITY MATRIX



Pin Contact

Socket Contact

Size 12 for use with
-086 cable
40 GHz SMPM interface
50 Ohm
Solder termination

Snap-in, rear release
pin and socket coax
contacts, spring-loaded.



962-025-086

BLUMARK
COAX CABLES RF


- 50 ohm size 086 (.104" jacket diameter, .020" conductor) 40 GHz max. bandwidth low-attenuation cable
- -65 to +150 °C rated operating temperature
- FEP jacket, LPCF dielectric, solid SPC center conductor
- Double-shielded: Tape/braid shield layers with >90 dB shield effectiveness



Series 23 SuperNine
"Better than QPL"
MIL-DTL-38999 Series III



Series 806 RF Mil-Aero
Micro miniature
circular IAW D38999

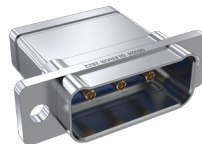

Series 795 RF
High-performance
multi-port rectangular



VITA 67.3 RF
VPX modular
connection system

852-099-01 Pin	✓	✓	✓	
852-154-01 Socket	✓			
852-100-01 Socket		✓	✓	
852-304-02 (Module, Center Pin)				✓
852-305-02 (Backplane, Center Socket)				✓